

	DATA SHEET	
Valid from: 21-01-2019	FLEXIMARK® LMB	

For wire and cable identification. Mounted in FLEXIMARK® collars. Delivered on perforated sheets designed for laser printing. UV-resistant.



Technical data:

Material:	Polyester, halogen free, UV-resistant
Operating temperature:	-40°C to +125°C
Sheet size:	A5
Colour:	Yellow/White
Recommended storage:	21°C and 50% RH

Mounting:

Mounted in FLEXIMARK® collars.

Other product data:

ETIM Classification:	EC001288
----------------------	----------

Advantages:

Supplied as punched and perforated A5 sheets.
 Printed in standard office laser printers, both sides are printable.
 Easy mounting.


	DATA SHEET	
Valid from: 21-01-2019	FLEXIMARK® LMB	

Product data:

E-nr.	LAPP Part no.	Article designation	Size/ Label WxH mm	colour	Content (sheet)	Content /unit	PU
2972084	83254680	LMB 30x4.6 mm ye/wh	30x4,6	Yellow/White	48	480	1

Related products

FLEXIMARK® LMB labels can be printed using FLEXIMARK® Software and an office laser printer. Select label in the label selector in the program, add to the table what to print, select printer and print.

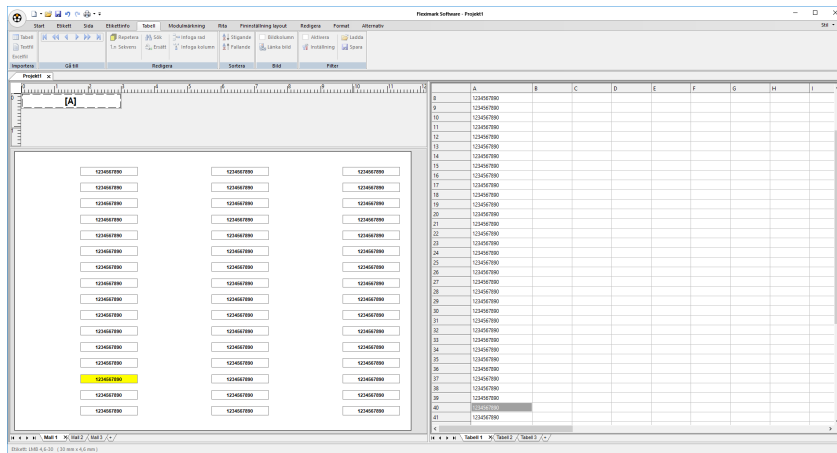

FLEXIMARK® Collar Snap-On for simple and effective snap-on mounting. Comes in different sizes.



Note:

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83254680EN Version: 01	Page 2 of 2
-----------------------	---------------------------------------	-------------