


|                           |                               |   |
|---------------------------|-------------------------------|---|
| 79165200                  | <b>DATA SHEET</b>             |  |
| Valid from:<br>17.09.2018 | <b>EPIC® H-B 24 SDR LH-LB</b> |   |

## Description

- Ideal for many applications due to a wide range of housings and inserts



## General Characteristics

|                              |   |
|------------------------------|---|
| Series                       | H-B 24  |
| Version                      | Surface mount base M25 / M32 (Article 79165400) |
| Protection cover             | Yes   |
| Locking                      | Single lever                                    |
| Cable entry                  | 2   |
| Protection (DIN EN 60529)    | IP 65 (latched)                                 |
| Protection (NEMA 250, UL50E) | 12 (latched)                                    |
| Temperature Range            | -40°C to +100°C, short term up to +125°C        |

## Materials and Surfaces

|         |                                      |
|---------|--------------------------------------|
| Housing | Aluminium alloy, powder-coated, grey |
| Cover   | Zinc alloy, powder-coated, grey      |
| Bolt    | Heat-treatable steel, zinc-plated    |
| Lever   | Steel, zinc-plated                   |
| Sealing | NBR                                  |


## Approvals

|                            |      |
|----------------------------|------|
| VDE-Approval, VDE-REG.-Nr. | B437 |
|----------------------------|------|


## Standard

|                 |           |
|-----------------|-----------|
| Safety Standard | IEC 61984 |
|-----------------|-----------|

|   |                                       |             |
|---|---------------------------------------|-------------|
| Creator: MANA2/PDP<br>Released: IVSE1/PDP | Document: DB79165200EN<br>Version: 01 | Page 1 of 2 |
|---|---------------------------------------|-------------|

|                           |                        |   |
|---------------------------|------------------------|---|
| 79165200                  | <b>DATA SHEET</b>      |  |
| Valid from:<br>17.09.2018 | EPIC® H-B 24 SDR LH-LB |   |

### Technical Drawings

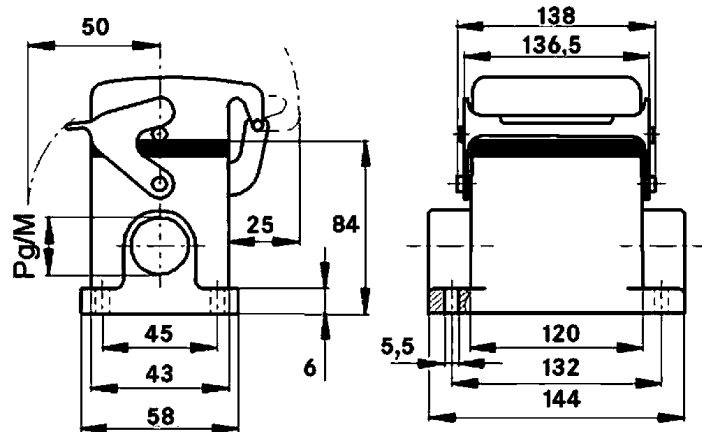

Automation



Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof

### Info

Universal, robust metal housings size H-B 24

### Application range

Plant engineering  
Light & sound technology  
Plastics industry

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

|   |                                       |             |
|---|---------------------------------------|-------------|
| Creator: MANA2/PDP<br>Released: IVSE1/PDP | Document: DB79165200EN<br>Version: 01 | Page 2 of 2 |
|---|---------------------------------------|-------------|