

51730200	<b>DATA SHEET</b>	
Valid from: 08.02.2023	<b>SKINDICHT® VENT</b>	

SKINDICHT® VENT is a pressure compensation element, made of polyamide or stainless steel, with a breathable and waterproof special membrane.




**Material:**

Gland body	Polyamide / Stainless steel (1.4305)
O-Ring	NBR
Membrane	Acryl-CoPolymer

**Technical Features:**

Connecting thread	M12x1,5 acc. to EN 60423
Protection class	SKINDICHT VENT IP66, IP68 and IP69 acc. to EN 60529 SKINDICHT VENT PLUS IP66, IP67 and IP69 acc. to EN 60529
Temperature range	Polyamide -20°C up to +100°C Stainless steel -40°C up to +105°C

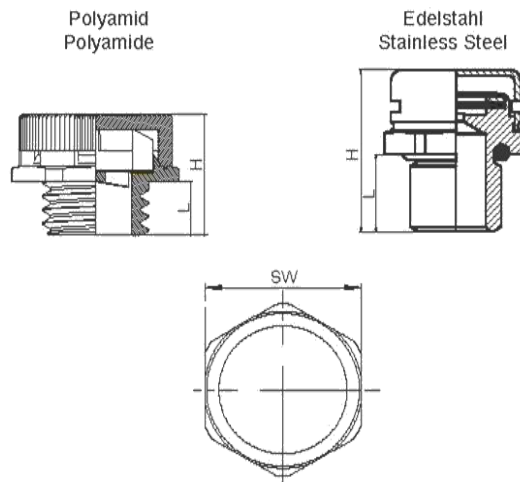

Part No.	Description	Colour	Connecting thread	Thread length L mm	Length H mm	Wrench size SW	Air flow 100mbar
<b>SKINDICHT® VENT INOX</b>							
5173 0204	-	-	M12x1,5	10	21,0	17	0,4 l/min
5173 0205	Plus	-	M12x1,5	10	21,0	17	2,4 l/min
<b>SKINDICHT® VENT PA6</b>							
5173 0200	-	Black (RAL9005)	M12x1,5	10	17,6	17	0,8 l/min
5173 0202	-	Light grey (RAL 7035)	M12x1,5	10	17,6	17	0,8 l/min
5173 0201	Plus	Black (RAL9005)	M12x1,5	10	17,6	17	3,5 l/min
5173 0203	Plus	Light grey (RAL 7035)	M12x1,5	10	17,6	17	3,5 l/min

Creator: MOME3 /PDP Released: DAMU1/PDP	Document: DB51730200EN Version: 09	Page 1 of 1
--	---------------------------------------	-------------