


55506485	DATA SHEET	
Valid from: 03.07.2018	SILVYN® FPAG 90° M	

SILVYN® FPAG 90° M is a conduit gland with a fast fit for a safety assembling.
 For the demounting we are recommending to use a screwdriver.
 The gland is suitable for SILVYN® FPAS and can be used in the machine- and plant constructions.




- Material:** PA 66
- Features:** Fast assembly
 Anti-vibration
 Suitable for fine and coarse conduits
 High mechanical strength
- Temperature range:** -50°C up to +135°C
- Colour:** Grey
 Black (UV-Resistant)


Norm Reference:    **UL FILENUMBER E308201**

Note: Free of Halogen, Sulphur and Phosphorous

Protection class: IP 66

Creator: M. Wegerer /PDP Released: DAMU1/PDP	Document: DB55506485EN Version: 05	Page 1 of 2
---	---------------------------------------	-------------

55506485	DATA SHEET	
Valid from: 03.07.2018	SILVYN® FPAG 90° M	

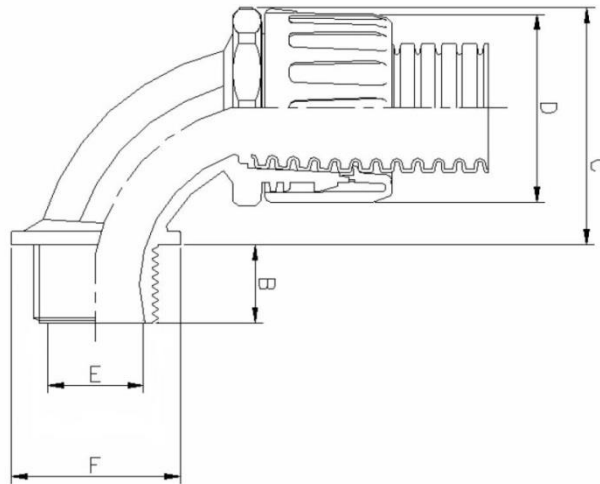

Dimension table:

Part No.	Part name	NW	Length C mm	Thread Length B mm	Inner Ø E mm	Outer Ø D mm	Ø F mm
Grey							
5550 6480	SILVYN® FPAG 90° M12x1,5 GY	10	24	8	6,5	19	17
5550 6490	SILVYN® FPAG 90° M16x1,5/1 GY	13	35	11	10,5	24	22
5550 6500	SILVYN® FPAG 90° M16x1,5/2 GY	16	38	11	10,5	29	22
5550 6510	SILVYN® FPAG 90° M20x1,5/1 GY	16	38	13	14	29	27
5550 6520	SILVYN® FPAG 90° M20x1,5/2 GY	18	40	13	14	32	27
5550 7070	SILVYN® FPAG 90° M20x1,5/3 GY	21	40	13	14	32	27
5550 6530	SILVYN® FPAG 90° M25x1,5 GY	28	51	15	19	44	32
5550 6540	SILVYN® FPAG 90° M32x1,5 GY	34	59	16	24,5	51	40
5550 7080	SILVYN® FPAG 90° M40x1,5 GY	42	82	16	32,5	63	50
5550 6550	SILVYN® FPAG 90° M50x1,5/1 GY	42	83	16	39	63	60
5550 6560	SILVYN® FPAG 90° M50x1,5/2 GY	54	88	16	39	76	60
5550 6570	SILVYN® FPAG 90° M63x1,5/1 GY	54	88	16	49,5	76	72
5550 7090	SILVYN® FPAG 90° M63x1,5/2 GY	67	104	16	49,5	90	72
Black							
5550 6485	SILVYN® FPAG 90° M12x1,5 BK	10	24	8	6,5	19	17
5550 6495	SILVYN® FPAG 90° M16x1,5/1 BK	13	35	11	10,5	24	22
5550 6505	SILVYN® FPAG 90° M16x1,5/2 BK	16	38	11	10,5	29	22
5550 6515	SILVYN® FPAG 90° M20x1,5/1 BK	16	38	13	14	29	27
5550 6525	SILVYN® FPAG 90° M20x1,5/2 BK	18	40	13	14	32	27
5550 7075	SILVYN® FPAG 90° M20x1,5/3 BK	21	40	13	14	32	27
5550 6535	SILVYN® FPAG 90° M25x1,5 BK	28	51	15	19	44	32
5550 6545	SILVYN® FPAG 90° M32x1,5 BK	34	59	16	24,5	51	40
5550 7085	SILVYN® FPAG 90° M40x1,5 BK	42	82	16	32,5	63	50
5550 6555	SILVYN® FPAG 90° M50x1,5/1 BK	42	83	16	39	63	60
5550 6565	SILVYN® FPAG 90° M50x1,5/2 BK	54	88	16	39	76	60
5550 6575	SILVYN® FPAG 90° M63x1,5/1 BK	54	88	16	49,5	76	72
5550 7095	SILVYN® FPAG 90° M63x1,5/2 BK	67	104	16	49,5	90	72

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: M. Wegerer /PDP Released: DAMU1/PDP	Document: DB55506485EN Version: 05	Page 2 of 2
---	---------------------------------------	-------------