


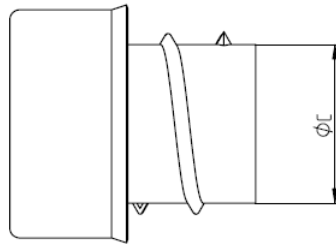
| | | |
|---------------------------|--------------------------|---|
| 61802480 | DATA SHEET |  |
| Valid from: 03.07.2018 | SILVYN® US-EDU-AS | |

SILVYN® US-EDU-AS is an inner- / end sleeve for the installing form protection conduits on the gland SILVYN® US or as an end sleeve to prevent cable from being damaged, when there is no gland installation.



Material: Brass

Temperature range: -40°C up to +250°C



Dimension table:

| Part No. | Part name | Nominal size | Conduit diameter mm | | Diameter C mm |
|-----------|------------------------|--------------|---------------------|-------|---------------|
| | | | Inner | Outer | |
| 6180 2480 | SILVYN® US-EDU-AS 7 | 10 | 7,0 | 10,0 | 6,0 |
| 6180 2490 | SILVYN® US-EDU-AS 9 | 14 | 10,0 | 14,0 | 8,5 |
| 6180 2500 | SILVYN® US-EDU-AS 11 | 17 | 13,0 | 17,0 | 11,5 |
| 6180 2510 | SILVYN® US-EDU-AS 13,5 | 19 | 15,0 | 19,0 | 13,5 |
| 6180 2520 | SILVYN® US-EDU-AS 16 | 21 | 17,0 | 21,0 | 15,5 |
| 6180 2530 | SILVYN® US-EDU-AS 21 | 27 | 22,0 | 27,0 | 20,5 |
| 6180 2540 | SILVYN® US-EDU-AS 29 | 36 | 29,0 | 36,0 | 27,5 |
| 6180 2550 | SILVYN® US-EDU-AS 36 | 45 | 38,0 | 45,0 | 36,5 |
| 6180 2570 | SILVYN® US-EDU-AS 48 | 56 | 49,0 | 56,0 | 47,5 |

Suitable conduits: SILVYN® AS-P
SILVYN® EDU-AS
SILVYN® EMC AS-CU

Suitable gland: SILVYN® US
SILVYN® US-M

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

| | | |
|---|---------------------------------------|-------------|
| Creator: M. Wegerer /PDP Released: DAMU1/PDP | Document: DB61802480EN Version: 02 | Page 1 of 1 |
|---|---------------------------------------|-------------|